


Passive guide axis

FDG-50- -

Part number: 192854

FESTO

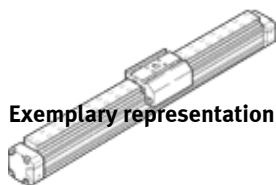

Exemplary representation

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Size	50
Stroke	10 ... 3,000 mm
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide axis without actuator
Max. speed	3 m/s
Corrosion resistance classification CRC	0 - No corrosion stress
Ambient temperature	-10 ... 60 °C
Materials note	Free of copper and PTFE
Materials information for guide component	Steel
Materials information, housing	Wrought Aluminum alloy Anodized