


Passive guide axis FDG-63- -

Part number: 192855
Product to be discontinued

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

FESTO

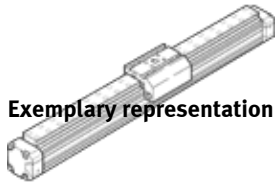

Exemplary representation

Data sheet

Overall data sheet – Individual values depend upon your configuration.

| Feature | Value |
|---|------------------------------------|
| Size | 63 |
| Stroke | 1 ... 4,500 mm |
| Assembly position | Any |
| Guide | Recirculating ball bearing guide |
| Design structure | Guide axis without actuator |
| Max. speed | 3 m/s |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| Ambient temperature | -10 ... 60 °C |
| Materials note | Free of copper and PTFE |
| Material of guide component | Steel |
| Material housing | Wrought Aluminum alloy Anodized |