


AS-i module

ASI-EVA-4E-M12-5POL

Part number: 197069

FESTO

AS interface for 4 sensor inputs

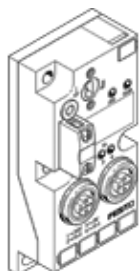

Data sheet

Feature	Value
Polarity protected	for operating voltage
DC operating voltage, AS interface	26.5 ... 31.6 V
Maximum number of inputs	4
Residual ripple, AS interface	20 mVss
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Storage temperature	-20 ... 70 °C
Protection class	IP65
Ambient temperature	-5 ... 50 °C
Authorization	c UL us - Recognized (OL)
Product weight	200 g
Input characteristics	Per IEC 1131-2, type 02
Input circuit logic	PNP (positive-switching)
Mounting type	with through hole