


# Manifold block MHA1-PR10-3-M3-PI

Part number: 197226

FESTO

with base plugs, for manifold block valves MHA1-...-PI

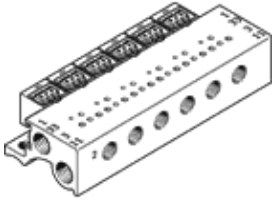

## Data sheet

Feature	Value
Max. number of valve positions	10
Working pressure	0 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Mounting method for subbase	with through hole
Mounting method for valve	with internal (female) thread
Pneumatic connection, port 1	M7
Pneumatic connection, port 2	M3
Pneumatic connection, port 3	M7
Material of connecting plate	Wrought Aluminum alloy