


Quick coupling plug KS4-CK-4

Part number: 2150

FESTO

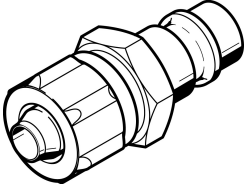

Data sheet

Feature	Value
Nominal width	2.9 mm
Operating pressure for entire temperature range	-0.95 bar...12 bar
Standard nominal flow rate	252 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	26 g
Pneumatic connection 1	CK-4
Note on materials	RoHS-compliant