 



Round cylinder EG-16-40

Part number: 2420

FESTO

With spring return

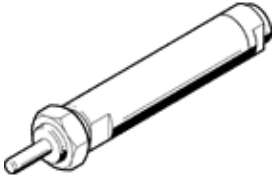

Data sheet

Feature	Value
Stroke	40 mm
Piston diameter	16 mm
Cushioning	No cushioning
Position detection	No
Variants	Single-ended piston rod
Working pressure	2 ... 8 bar
Mode of operation	single-acting pushing action
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Ambient temperature	-20 ... 80 °C
Theoretical force at 6 bar, advance stroke	121 N
Pneumatic connection	G1/8