


Sub-base VABP-S3-26V1G-G18-2

Part number: 2605074

FESTO

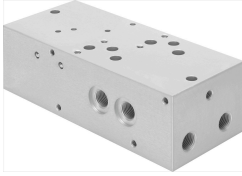

Data sheet

| Feature | Value |
|----------------------------------|---|
| Width | 26 mm |
| Function port 32 | G1/8 |
| Function port 34 | G1/8 |
| Pneumatic connection 22 | Sub-base G1/8 |
| Pneumatic connection 44 | Sub-base G1/8 |
| Mounting position | Any |
| Operating pressure | 0 bar...16 bar |
| Standard nominal flow rate | 800 l/min |
| Operating medium | Compressed air as per ISO 8573-1:2010 [6:4:4] |
| Corrosion resistance class (CRC) | 0 - No corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Temperature of medium | 0 °C...50 °C |
| Ambient temperature | 0 °C...50 °C |
| Product weight | 668 g |
| Pilot air port 14 | M5 |
| Pneumatic connection 2 | G1/8 |
| Pneumatic connection 4 | G1/8 |
| Note on materials | RoHS-compliant |
| Manifold rail material | Wrought aluminum alloy |
| O-ring material | NBR |
| Material of screws | Steel |