


Rod clevis SG-M10

Part number: 2674

FESTO

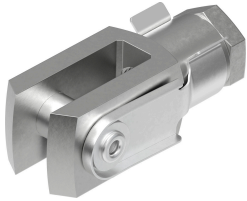

Data sheet

Feature	Value
Size	M10
Based on norm	ISO 8140
Conforms to standard	DIN 71752
Threaded connection	Internal thread M10
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 1% copper by mass are excluded from use. Exception are printed circuit boards, cables, electrical connectors and coils
Ambient temperature	-40 °C...150 °C
Product weight	104 g
Note on materials	RoHS-compliant
Bolt material	Steel Galvanized
Clevis material	Steel Galvanized
Nut material	Steel Galvanized