


# Bellows kit EADB-V2-32-S301-400

Part number: 2828832

FESTO

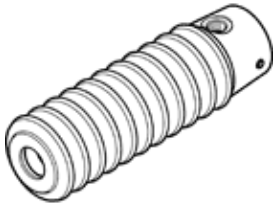

## Data sheet

Feature	Value
Outside diameter	57 mm
Size	32
Stroke range	301 ... 400 mm
Piston rod extension	121 mm
Design	Round
Assembly position	Any
Design structure	Bellows kit with ducted exhaust air
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B2-L
Resistance to media	Dust Chippings Oils Grease Gasolines
Protection class	IP65 to IEC 60529
Ambient temperature	-10 ... 80 °C
Moving mass	143 g
Product weight	212 g
Mounting type	slip-on With threaded pin
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material adapter components	Wrought Aluminum alloy Anodized
Material seals	NBR
Material bellows	NBR
Material threaded pin	High alloy steel, non-corrosive