


Series subbase VIGK-04-D-1

Part number: 30424

FESTO

For valve manifold

Type to be discontinued. Available until 2011.

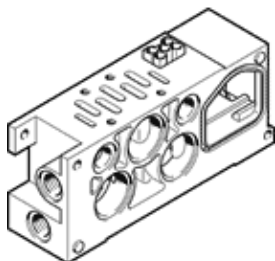

Data sheet

| Feature | Value |
|-----------------------------------|-------------------------|
| Based on the standard | ISO 5599-2 |
| Max. number of valve positions | 1 |
| Working pressure | -0.9 ... 16 bar |
| Operating medium | Filtered compressed air |
| Medium temperature | -10 ... 60 °C |
| Ambient temperature | -10 ... 60 °C |
| Authorization | UL - Recognized (OL) |
| Mounting method for subbase | with through hole |
| Pneumatic connection, port 1 | G1/2 |
| Pneumatic connection, port 2 | G1/4 |
| Pneumatic connection, port 3 | G1/2 |
| Pneumatic connection, port 4 | G1/4 |
| Pneumatic connection, port 5 | G1/2 |
| Materials information for subbase | Aluminum die cast |