


Connecting cable KDI-SB202-BU25

Part number: 30437

FESTO

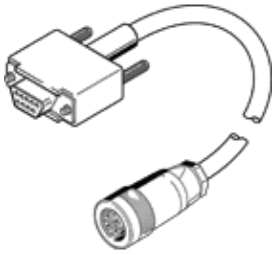

Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	≤ 300 V
Ambient temperature	-10 ... 80 °C -30 ... 80 °C
Product weight	210 g
Electrical connection	Straight socket / straight socket M12x1 / Sub-D 5-pin / 25-pin
Cable structure	4 x 0,14 mm ²
Cable diameter	4.5 ... 6.5 mm
Cable length	5 m
Mounting type	With sleeve nut Clip
Materials information for locknut	Brass Nickel plated
Materials information, housing	PBT
Materials information, cable sheaths	PUR
Material information for crimp connectors	Copper alloy Gold plated