


Barbed T fitting TCN-M3-PK-2

Part number: 30492

FESTO

Rotatable, for metric series plastic tubing PAN, PUN, PP, PU, PR, with sealing ring.

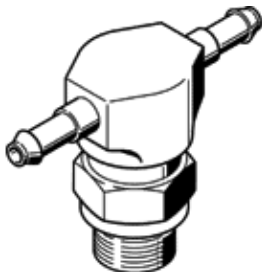

Data sheet

Feature	Value
Nominal size	1.3 mm
Type of seal on screw-in stud	Sealing ring
Operating pressure complete temperature range	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	0 ... 60 °C
Pneumatic connection, port 1	Male thread M3
Pneumatic connection, port 2	For tubing outside diameter 3 mm
Materials note	Conforms to RoHS
Material housing	Zinc die-casting High alloy steel, non-corrosive