


# Protective conduit connector threaded connector MKGV-23-M32-B

Part number: 3152612

FESTO

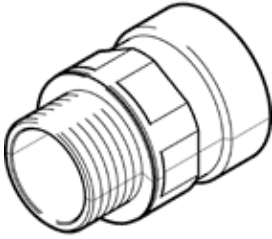

## Data sheet

Feature	Value
Assembly position	Any
Container size	100
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Protection class	IP54
Ambient temperature	-40 ... 100 °C
Mounting type	with external (male) thread
Materials note	Conforms to RoHS
Material fitting	PA