

 

# Solenoid valve

## MYH-5/2-M5-L-LED

Part number: 34309

FESTO

Mini Pneumatic, with solenoid coil and manual override, without socket.

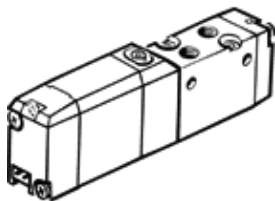

## Data sheet

Feature	Value
Valve function	5/2 single solenoid
Standard nominal flow rate	190 l/min
Working pressure	2 ... 8 bar
Design structure	Piston slide
Protection class	IP40 with plug socket
Nominal size	2.3 mm
Type of piloting	Piloted
Switching time off	23 ms
Switching time on	12 ms
Duty cycle	100%
Characteristic coil data	24V DC: 1,8W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	65 g
Mounting type	with through hole
Pneumatic connection, port 1	Subbase M5
Pneumatic connection, port 2	Subbase M5
Pneumatic connection, port 3	Subbase M5
Pneumatic connection, port 4	Subbase
Pneumatic connection, port 5	Subbase
Materials information for seals	NBR
Materials information, housing	Aluminum die cast