

 

# Bellows cylinder

## EB-215-80

Part number: 36488

FESTO

Maintenance-free, no stick/slip effect.

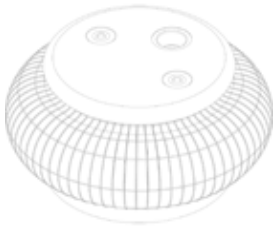

## Data sheet

Feature	Value
Size	215
Required installation diameter	230 mm
Stroke	80 mm
Max height when extended	135 mm
Max. tipping angle	20 deg
Max. offset	10 mm
Min. installation height	50 mm
Mode of operation	single-acting
Working pressure	0 ... 8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [-:~:4]
Note on operating and pilot medium	Lubricated operation not possible
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 70 °C
Reset force	200 N
Product weight	2,000 g
Mounting type	with internal (female) thread
Pneumatic connection	G3/4
Materials note	Conforms to RoHS
Material bellows	NR/BR
Material housing	Steel Galvanized