


# Non return valve H-M5

Part number: 3671

FESTO

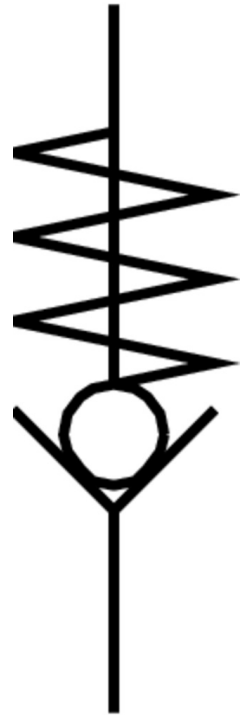

## Data sheet

Feature	Value
Valve function	Non-return function
Pneumatic connection 1	M5
Pneumatic connection 2	M5
Type of mounting	Line installation
Standard nominal flow rate	115 l/min
Operating pressure	0.04 MPa...0.8 MPa 0.4 bar...8 bar
Ambient temperature	-10 °C...60 °C
Housing material	Brass
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B2-L
Temperature of medium	-10 °C...60 °C
Note on materials	RoHS-compliant
Seals material	NBR