
 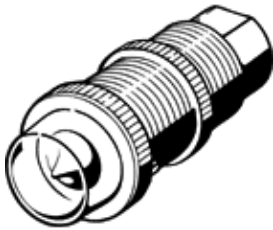


# Pressure indicator OH-22-RT

Part number: 4131

FESTO



## Data sheet

Feature	Value
Assembly position	Any
Working pressure	1.4 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 45 °C
Ambient temperature	-10 ... 45 °C
Product weight	25 g
Mounting type	Control panel installation in diameter 22.5
Pneumatic connection	G1/8
Materials note	Conforms to RoHS