


# Distributor block FR-12-M5

Part number: 4525

FESTO

For distribution of compressed air.

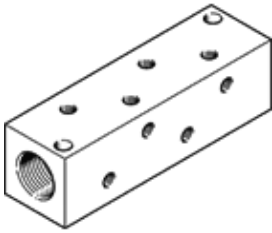

## Data sheet

Feature	Value
Nominal size	4.1 mm
Assembly position	Any
Operating pressure complete temperature range	0 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	3.5 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	40 g
Number of outputs	12
Number of supply lines	1
Pneumatic connection, port 1	Female thread G1/8
Pneumatic connection, port 2	Female thread M5
Materials note	Conforms to RoHS
Material housing	Aluminum Anodized