 



# Pushbutton valve T-5/3-1/4

Part number: 4578

FESTO

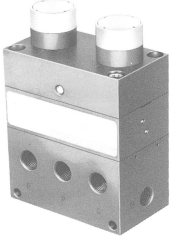

## Data sheet

Feature	Value
Valve function	5/3, closed
Actuation type	Manual
Standard nominal flow rate	680 l/min
Pneumatic working port	G1/4
Operating pressure	0.2 MPa...1 MPa 2 bar...10 bar
Nominal width	7 mm
Sealing principle	Soft
Type of control	Pilot-controlled
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	1160 g
Pneumatic connection 1	G1/4
Pneumatic connection 2	G1/4
Pneumatic connection 3	G1/4