

 

# Solenoid valve

## MLC-8-3/8-B

Part number: 4801  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2017. See Support Portal for alternative products.

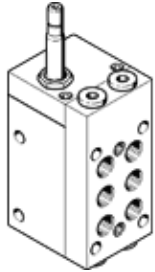

## Data sheet

Feature	Value
Valve function	8/2 monostable
Type of actuation	electrical
Standard nominal flow rate	1,800 l/min
Working pressure	2 ... 10 bar
Design structure	Piston slide
Type of reset	Air spring
Nominal size	9 mm
Sealing principle	soft
Assembly position	Vertical
Manual override	None
Pilot air supply	Internal
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation required
Medium temperature	-5 ... 40 °C
Ambient temperature	-10 ... 60 °C
Mounting type	with through hole
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 2	G3/8
Pneumatic connection, port 3	G3/8
Pneumatic connection, port 4	G3/8
Pneumatic connection, port 5	G3/8
Materials information for seals	NBR