


# Coupling EAMD-21-15-11-8X10

Part number: 4820350

FESTO

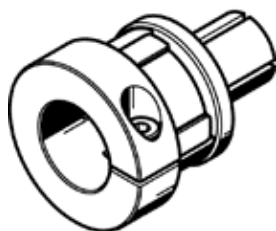

## Data sheet

| Feature                | Value                  |
|------------------------|------------------------|
| Holder diameter 1      | 11 mm                  |
| Holder diameter 2      | 8 mm                   |
| Size                   | 21                     |
| Nominal length         | 15 mm                  |
| Assembly position      | Any                    |
| Max. speed             | 10,000 1/min           |
| PWIS conformity        | VDMA24364-B2-L         |
| Storage temperature    | -25 ... 60 °C          |
| Relative air humidity  | 0 - 95 %               |
| Ambient temperature    | -25 ... 60 °C          |
| Mass moment of inertia | 0.45 kgmm <sup>2</sup> |
| Transferable torque    | 2 Nm                   |
| Product weight         | 13.7 g                 |
| Materials note         | Conforms to RoHS       |