

 

Proximity Sensor

SMT-8F-PO-24V-K7,5-OE

Part number: 525911

FESTO

Electrical, contactless, PNP, normally closed, for drive units with 8 mm sensor slot, top mounting, with cable.

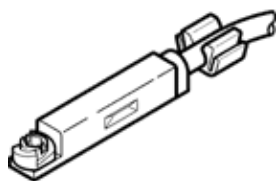

Data sheet

Feature	Value
Operating voltage range DC	10 ... 30 V
Switch output	PNP
Switching element function	Normally closed contact
Max. output current	100 mA
Cable length	7.5 m
Electrical connection	3-core Cable
Design	for T-slot
Short circuit strength	Yes
Measuring principle	Magnetoresistive
Polarity protected	for all electrical connections
Operating status display	Yellow LED
Switch-off time	11 ms
Switch-on time	0.5 ms
Max. contact rating DC	3 W
Residual current	0.1 mA
Voltage drop	1.8 V
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Protection class	IP65 IP67
Ambient temperature	-5 ... 60 °C -20 ... 60 °C
Tightening torque	0.6 Nm
Product weight	90 g
Reproducibility of switching value	+/- 0,1 mm
Mounting type	Clamped in T-slot
Materials note	Free of copper and PTFE
Materials information, housing	PA
Materials information, cable sheaths	PUR