

Pressure gauge


MA-50-36-N1/4-PSI-E-RG

Part number: 530389

FESTO

With display unit in psi, adjustable red/green range.

This product is only available if ordered from the Festo Corporation, USA.

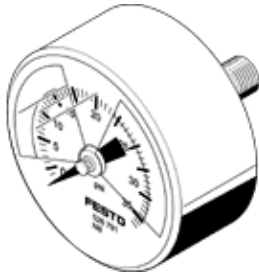

Data sheet

| Feature | Value |
|---|-------------------------------|
| Indicating range [psi] | 0 ... 36 psi |
| Conforms to standard | EN 837-1 |
| Nominal size of pressure gauge | 50 |
| Design structure | Bourdon-tube pressure gauge |
| Mounting type | Line installation |
| Operating medium | Inert gases Neutral fluids |
| Working pressure | 0 ... 36 Psi |
| Alternating load factor | 0.66 |
| Measurement accuracy class | 2,5 |
| Protection class | IP43 |
| Medium temperature | -20 ... 60 °C |
| Ambient temperature | -20 ... 60 °C |
| Materials note | Conforms to RoHS |
| Position of connection | Rear side central |
| Pneumatic connection | NPT1/4-18 |
| Materials in contact with media | Brass |
| Materials information for screw-in stud | Brass |
| Materials information, housing | ABS |
| Materials info, viewing window | PMMA |
| Housing color | Black |
| Product weight | 75 g |
| Note on operating and pilot medium | No oxygen No acetylene |