


# Quick coupling socket KD3-CN-6-S

Part number: 531632  
Product to be discontinued

FESTO

Self-closing, bulkhead fitting

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

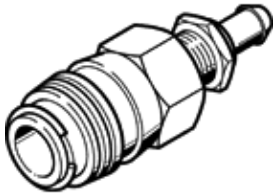

## Data sheet

Feature	Value
Nominal size	4.9 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	378 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	44 g
Pneumatic connection, port 1	CN-6
Materials note	Conforms to RoHS