

 

Silencer

U-1/4-20

Part number: 534223

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

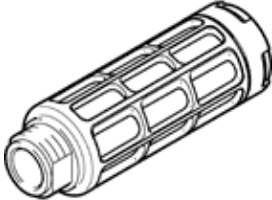

Data sheet

Feature	Value
Assembly position	Any
Container size	20
Operating pressure MPa	0 ... 1 MPa
Working pressure	0 ... 10 bar
Flow rate to atmosphere	3,300 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Note on operating and pilot medium	Lubricated operation possible
PWIS conformity	VDMA24364-B1/B2-L
Sound pressure level	76 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	7.7 g
Pneumatic connection	G1/4
Material of silencer insert	PE
Materials note	Conforms to RoHS