


# Vacuum filter

## VAF-PK-3

Part number: 535883

FESTO

In-line design.

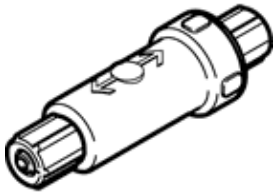

## Data sheet

| Feature   | Value  |
|---|--|
| Nominal size  | 2 mm   |
| Assembly position   | Any  |
| Grade of filtration   | 50 µm  |
| Working pressure  | -0.95 ... 0 bar  |
| Note on working pressure  | Only for application in open vacuum systems              |
| Flow rate at negative pressure of -0.075 MPa (-0.75 bar, -10.875 psi) | 50.8 l/min   |
| Operating medium  | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| PWIS conformity   | VDMA24364-B1/B2-L  |
| Ambient temperature   | 0 ... 40 °C  |
| Product weight  | 4 g  |
| Mounting type   | Line installation  |
| Pneumatic connection  | PK-3 with union nut                                      |
| Material of union nut   | POM  |
| Materials note  | Conforms to RoHS   |
| Material filter   | Mesh<br>PA   |
| Material housing  | PA   |
| Ejector pulse suitability   | ≤ 8 bar  |