


# Sub-base-SET MS12-AQU

Part number: 537140

FESTO

From the MS series, with NPT thread.

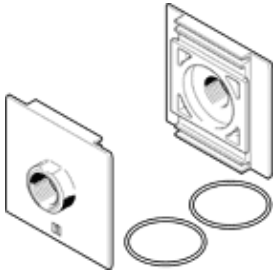

## Data sheet

| Feature                                 | Value                                      |
|---|--|
| Size                                    | 12   |
| Series                                  | MS   |
| Assembly position                       | Any  |
| Operating medium                        | Air quality class 5:7:- per DIN ISO 8573-1 |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress              |
| PWIS conformity                         | VDMA24364-B2-L                             |
| Storage temperature                     | -10 ... 60 °C                              |
| Medium temperature                      | -10 ... 60 °C                              |
| Product weight                          | 1,300 g                                    |
| Pneumatic connection, port 1            | 1 1/4 NPT                                  |
| Pneumatic connection, port 2            | 1 1/4 NPT                                  |
| Materials note                          | Conforms to RoHS                           |
| Material of connecting plate            | Aluminum die cast                          |
| Material seals                          | NBR  |