


Pneumatic shock absorber YSRW-DGC-40-GF

Part number: 540352

FESTO

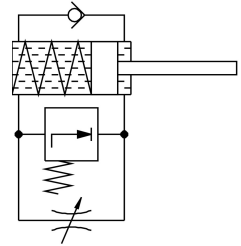

Data sheet

Feature	Value
Size	40
Cushioning	Self-adjusting Soft characteristic curve
Mounting position	Any
Position sensing	None
Max. impact velocity	3 m/s
Mode of operation	Single-acting Pushing
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...80 °C
Type of mounting	With lock nut
Note on materials	RoHS-compliant
Piston rod material	High-alloy steel