


Ball valve actuator unit VZPR-BPD-22-R212

Part number: 540874

FESTO

Brass, with double-acting drive DAPS 2/2-way, nominal width 2 1/2",
PN25, thread EN 10226-1.

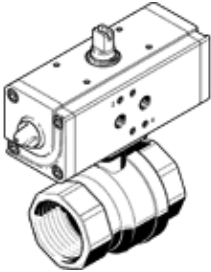

Data sheet

Feature	Value
Design structure	2-way ball valve Swivel actuator
Type of actuation	electrical pneumatic
Assembly position	Any
Mounting type	CNOMO with internal (female) thread
Process valve connection	Rp2 1/2
Switching position indicator	Knob direction = Flow direction
Nominal diameter DN	63
Working pressure, ball valve actuator	1 ... 8.4 bar
Nominal pressure of process valve	25
Medium temperature	-20 ... 150 °C
Ambient temperature	-20 ... 80 °C
PWIS conformity	VDMA24364 zone III
Product weight	7,300 g
Corrosion resistance classification CRC	1 - Low corrosion stress