


# Solenoid coil

## VACN-N-K11-16B-0.5-U4-M

Part number: 541666

FESTO

Cable with insulating conduit connection, 120 V AC/60 Hz and 110 V AC/50-60 Hz

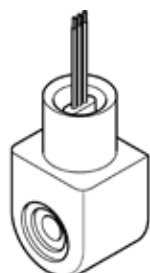

### Data sheet

Feature	Value
Characteristic coil data	110 V AC: 50 Hz, pick-up power 12.5 VA, holding power 7.5 VA 120 V AC: 60 Hz, pick-up power 11.5 VA, holding power 6.5 VA
Permissible voltage fluctuation	+/- 10 %
Explosion protection certification outside the EU	NEC 500 Class I, Div. 1
Corrosion resistance classification CRC	1
Protection class	IP65
Ambient temperature	-20 ... 60 °C
Cable length	0.5 m
Materials note	Conforms to RoHS