


AS-i module

ASI-4DI3DO-M12X2-5POL-Z

Part number: 542125

FESTO

enables the connection of 4 sensors and 3 actuators, with M12 connection technology.

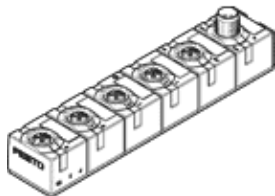

Data sheet

Feature	Value
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU-Ex protection guideline (ATEX) in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK EX instructions To UK RoHS instructions
KC mark	KC-EMV
Authorization	c UL us - Listed (OL)
ATEX category Gas	II 3G
ATEX category Dust	II 3D
Explosion protection certification outside the EU	EPL Dc (GB) EPL Gc (GB)
Explosion ignition protection type Gas	Ex ec IIC T4 Gc X
Explosion ignition protection type Dust	Ex tc IIIC T115°C IP67 Dc X
Explosion-proof ambient temperature	-5°C ≤ Ta ≤ +50°C