


# Parallel kit EAMM-U-E48-70A

Part number: 543234

FESTO

Suitable for electric drives.

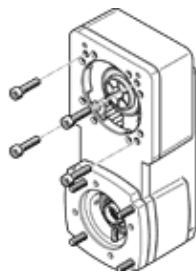

## Data sheet

Feature	Value
Size	40
Assembly position	Any
Max. speed	3,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	71.138 kgmm <sup>2</sup>
No-load driving torque	0.3 Nm
Transferable torque	5.5 Nm
Product weight	1,300 g
Materials note	Contains PWIS substances