


Basic valve LOE-D-MINI-U

Part number: 546431

FESTO

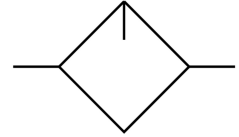

Data sheet

Feature	Value
Size	Mini
Series	D
Mounting position	Vertical +/- 5°
Structural design	Proportional standard oil mist lubricator
Max. oil capacity	1,53 fl oz (US)
Bowl guard	Metal bowl guard
Operating pressure	0 psi...240 psi
Standard nominal flow rate	45,5 cfm
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	14 °F...140 °F
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:4:-] Inert gas
Temperature of medium	14 °F...140 °F
Ambient temperature	14 °F...140 °F
Product weight	7595 oz
Type of mounting	With accessories
Note on materials	RoHS-compliant