

# T fitting


## NPFB-T-R38-2G38-MFF

Part number: 547754

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminum AL 99.5 can also be used.

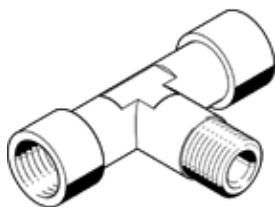

## Data sheet

| Feature                                   | Value   |
|---|---|
| Material information for threaded fitting | Brass<br>Nickel plated                                  |
| Container size                            | 10  |
| Working pressure                          | -0.95 ... 40 bar  |
| Operating medium                          | Compressed air in accordance with ISO8573-1:2010 [-:::] |
| Corrosion resistance classification CRC   | 1   |
| Ambient temperature                       | -20 ... 150 °C  |
| Product weight                            | 83 g  |
| Pneumatic connection, port 1              | R3/8  |
| Pneumatic connection, port 2              | G3/8  |
| Materials note                            | Conforms to RoHS  |