


# Socket connector KMYZ-4-0.0-B-EX

Part number: 550806

FESTO

Combination of MSZB and MSZC connection.

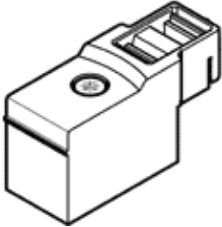

## Data sheet

Feature	Value
Assembly position	Any
Operating voltage range DC	3 ... 36 V
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	1
Protection class	IP40 to IEC 60529
Ambient temperature	-10 ... 50 °C
Authorization	Germanischer Lloyd
Product weight	6.5 g
Electrical connection	Plug socket angled Rectangular design, MSZB
Nominal conductor cross-section	0.22 ... 0.34 mm <sup>2</sup>
Mounting type	On solenoid valve with self-tapping screw
Materials note	Conforms to RoHS
Materials information, housing	PA
Material information for crimp connectors	Bronze