


# Output module CECX-D-14A-2

Part number: 552097

FESTO

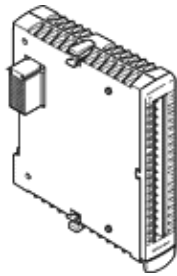

## Data sheet

Feature	Value
Corrosion resistance classification CRC	0 - No corrosion stress
Materials note	Contains PWIS substances Conforms to RoHS
Operating voltage	24 VDC +25% / -15%
Power consumption at system bus	0.4 W
Ambient temperature	5 ... 55 °C
Storage temperature	-40 ... 70 °C
Relative air humidity	10 - 95 %
Protection class	IP20
Safety class	III
Product weight	135 g
Test for insensitivity to vibration	EN 60068-2-6 FC 5 - 9 Hz 3,5 mm 9 - 150 Hz 1g
Test for insensitivity to shock	EN 60068-2-27 EA 15 g, 11 ms (half sine)
Electrical connector technology, I/O	Socket strip, grid 5.08 mm
Digital outputs, number	14
Digital outputs, switching logic	Positive logic (PNP)
Digital outputs, contact	Transistor
Digital outputs, output voltage	24 VDC
Digital outputs, output current	2 A for 50 % simultaneity per group
Digital outputs, electrical isolation	Yes, via optocoupler
Digital outputs, electrical isolation in groups	Yes, in 2 groups
Digital outputs, short circuit proof	Yes
Digital outputs, status display	LED