


Bellows kit DADB-S1-63-S251-300

Part number: 553509

FESTO

For standard cylinders to ISO 6432

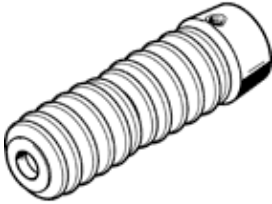

Data sheet

Feature	Value
Outside diameter	57 mm
Size	63
Stroke range	251 ... 300 mm
Piston rod extension	88 mm
Design	Round
Assembly position	Any
Design structure	Bellows kit with ducted exhaust air
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B2-L
RSBP classification to CD-0033	F5a
Resistance to media	Dust Chippings Oils Grease Gasolines
Protection class	IP54
Ambient temperature	-10 ... 80 °C
Product weight	131 g
Mounting type	With threaded pin with internal (female) thread
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material adapter components	PA-reinforced
Material seals	NBR
Material bellows	NBR
Material threaded pin	High alloy steel, non-corrosive