


Plug NECC-L1G6-C1

Part number: 553859

FESTO

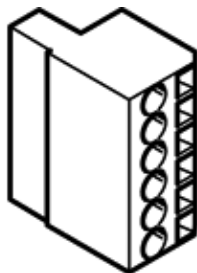

Data sheet

| Feature | Value |
|---|-----------------------------|
| Operating voltage range AC | 300 V |
| Permissible current load | 10 A |
| Terminal cross-section | 0.2 ... 2.5 mm ² |
| Ambient temperature | -25 ... 100 °C |
| Degree of contamination | 3 |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| Material housing | PBT |