


# Encoder cable NEBM-T1G12-T1G12-2.5

Part number: 556795

FESTO

For connecting the motor and controller

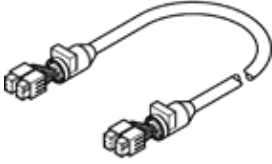

## Data sheet

Feature	Value
Cable attribute	Suitable for chain link trunking
Degree of contamination	3
Protection class	in assembled condition IP65
Ambient temperature with flexible cable installation	-40 ... 90 °C
Ambient temperature	-50 ... 90 °C
Min. cable bending radius	82 mm
Cable structure	Shielded 5 x (2 x 0,34 mm <sup>2</sup> ) + 2 x 0,5mm <sup>2</sup>
Cable diameter	11 mm
Cable length	2.5 m
Materials note	Contains PWIS substances Conforms to RoHS
Materials information, cable sheaths	TPE-U(PUR)