


Drive shaft EAMB-44-7-35X30-32X32

Part number: 558038

FESTO

for adapting drives with hollow shaft

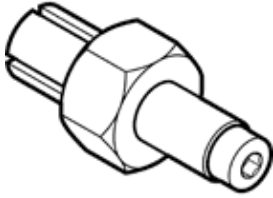

Data sheet

Feature	Value
Holder diameter 1	35 mm
Holder diameter 2	32 mm
Size	185
Nominal length	30 mm
Assembly position	Any
Max. speed	4,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	75.3 kgmm ²
Transferable torque	200 Nm
Product weight	463 g
Materials note	Conforms to RoHS