


Connecting cable VMPAL-KM-S-SD25-IP67-2.5

Part number: 560419

FESTO

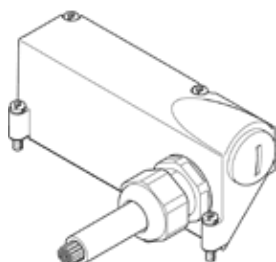

Data sheet

Feature	Value
Product weight	645 g
Electrical connection	Cable with plug
Cable length	2.5 m
Cable attribute	Standard
Min. cable bending radius	122 mm
Cable diameter	10.2 mm
Cable structure	25x0,34
Protection class	IP67 to IEC 60529
Ambient temperature with flexible cable installation	-5 ... 80 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B1/B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	PVC