


# Electrical manifold module VMPAL-EVAP-20-1

Part number: 560965

FESTO

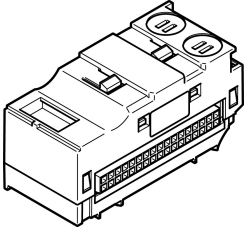

## Data sheet

Feature	Value
Valve size	20 mm
Max. no. of valve positions	1
Max. no. of solenoid coils	1
Integrated function	Valve function assignment color-coded
Nominal operating voltage DC	24 V
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	14 g
Housing colour	Gray
Housing material	PA
Note on materials	RoHS-compliant