


Electrical manifold module VMPAL-EVAP-10-2-4

Part number: 560968

FESTO

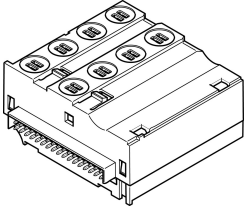

Data sheet

Feature	Value
Valve size	10 mm
Max. no. of valve positions	4
Max. no. of solenoid coils	8
Integrated function	Valve function assignment color-coded
Nominal operating voltage DC	24 V
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	29 g
Housing colour	Black
Housing material	PA
Note on materials	RoHS-compliant