


# Axial kit EAMM-A-P6-38A-42A

Part number: 562644

FESTO

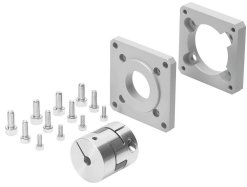

## Data sheet

Feature	Value
Mounting position	Any
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transferable torque	3.5 Nm
Product weight	160 g
Interface code, actuator	P6-38A
Interface code, motor in	42A
Interface code, coupling housing	38A.2
Note on materials	RoHS-compliant