


# Connecting cable NEBV-S1W25-K-10-N-LE25

Part number: 565285

FESTO

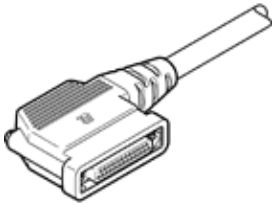

## Data sheet

Feature	Value
Assembly position	Any
Cable attribute	For static applications
Operating voltage range DC	$\leq 24$ V
Acceptable current load at 40°C	1.64 A
Protection class	IP65
Ambient temperature with flexible cable installation	-5 ... 80 °C
Ambient temperature	-40 ... 80 °C
Product weight	1,500 g
Electrical connection	25-pin Plug socket Sub-D
Cable structure	25 x 0,25 mm <sup>2</sup>
Cable diameter	9,9 mm
Cable length	10 m
Mounting type	4-40UNC
Materials note	Conforms to RoHS
Materials information, housing	TPE
Materials information, cable sheaths	PVC
Material information for crimp connectors	Bronze Gold plated