


Electrical sub-base VAVE-L1-1VL3-LP

Part number: 566724

FESTO

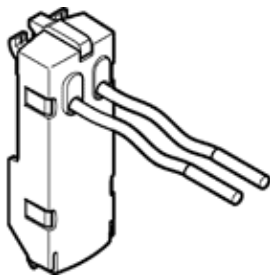

Data sheet

Feature	Value
Polarity protected	Bipolar
Additional functions	Spark arresting
Signal status display	LED
Nominal operating voltage DC	24 V 12 V
Surge strength	0.8 kV
Degree of contamination	3
Extended ambient temperature	-5 - 60 °C
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP40
Ambient temperature	-5 ... 50 °C
Assembly position	Any
Product weight	17.5 g
Terminal cross-section	0.14 mm ²
Electrical connection	Stranded wire
Cable length	2.5 m
Wire ends	Wire end ferrule
Protective earth connection	Not available
Mounting type	Clip
Housing color	Black
Materials note	Conforms to RoHS
Material housing	PA