


# Manifold strip

## VABM-B6-E-N12-8-M1

Part number: 568183

FESTO

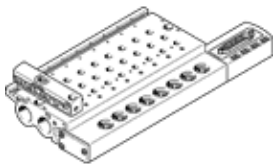

### Data sheet

Feature	Value
Grid dimension	21 mm
Max. number of valve positions	8
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Max. tightening torque, H-rail mounting	1.5 Nm
Max. tightening torque, valve mounting	2 Nm
Max. tightening torque, wall mounting	5 Nm
Product weight	1,150 g
Auxiliary pilot air port 12/14	NPT1/8-27
Pneumatic connection, port 1	NPT1/2-14
Pneumatic connection, port 3	NPT1/2-14
Materials note	Free of copper and PTFE Conforms to RoHS
Material manifold	Wrought Aluminum alloy