


Plug FBS-SCRJ-PP-GS

Part number: 571017

FESTO

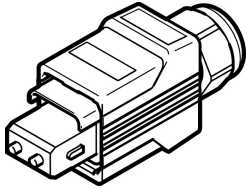

Data sheet

Feature	Value
Product weight	60 g
Note on fieldbus interface	PROFINET FOC
Ethernet cable specification	Fiber-optic cable 980/1000 µm polymer fiber Individual wire diameter: 2.2 mm
Approved cable diameter	6.5 mm...9.5 mm
Degree of protection	IP65 IP67 as per IEC 60529
Ambient temperature	-40 °C...70 °C
Storage temperature	-40 °C...70 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	1 - Low corrosion stress
Housing material	Die-cast zinc Nickel-plated
Seals material	NBR TPE