


# Plastic tubing

## PAN-MF-4X0,75-SW-500

Part number: 572091

FESTO

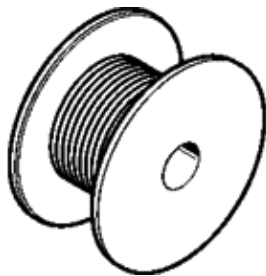

### Data sheet

Feature	Value
Outside diameter	4 mm
Bending radius relevant for flow rate	15 mm
Inside diameter	2.5 mm
Min. bending radius	10 mm
Conforms to standard	DIN 73378-PA12-PHL
Tubing characteristics	Suitable for energy chains
Temperature-dependent operating pressure	-0.095 ... 3.1 MPa
Temperature dependent working pressure	-0.95 ... 31 bar
Temperature-dependent operating pressure	-13.775 ... 449.5 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Mineral oil
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-60 ... 100 °C
Product weight according to length	0.008 kg/m
Pneumatic connection	For push-in connector outside diameter 4 mm
Color	Black
Shore hardness	D 65 +/-3
Materials note	Conforms to RoHS
Material tubing	Polyamide 12