


Adapter VAVE-C8-1R1

Part number: 573194

Classic - do not use for new projects

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

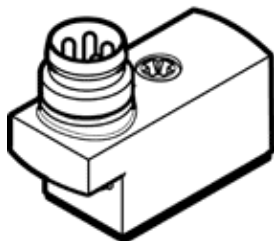

Data sheet

Feature	Value
Signal status display	LED
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 to IEC 60529
Ambient temperature	-5 ... 60 °C
Assembly position	Any
Tightening torque	0.25 Nm
Product weight	3.5 g
Electrical connection	4-pin/2-pin M8 / - Plug / socket
Protective earth connection	Not available
Mounting type	On solenoid valve with M2 central screw
Materials note	Conforms to RoHS
Material housing	PA
Material electrical contact	Bronze